



Designer Switches & Outlets Catalog


#LegrandImprovingLives





the
adorne[®]
collection


Dimmers & Switches

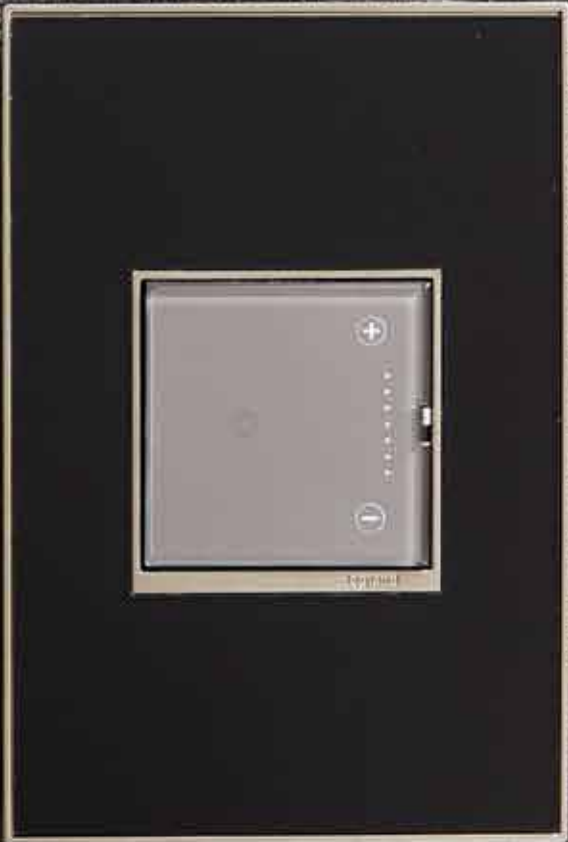

SOFTAP® TRU-UNIVERSAL DIMMER | ADTP703TUW4
This dimmer self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V). Turn lights on/off with a light push action.

PADDLE LED ADVANCED DIMMER | ADPD153LW2
Upgrade from a standard switch or dimmer to turn lights on/off with an easy up-or-down action, or use the slider to adjust light level.

PADDLE FAN SPEED CONTROL | AAFN4S16AW4
Adjust fan speed with modern style.

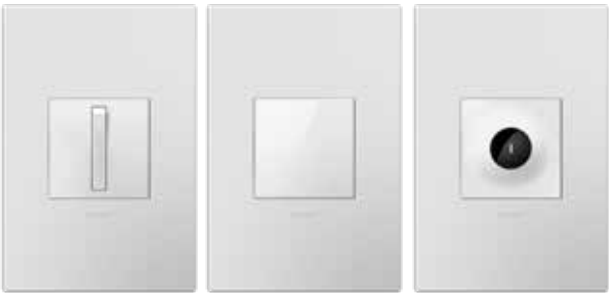


WHISPER® SWITCH | ASWR1532W4
Turn lights on/off with a fluid, gentle action.

TOUCH SWITCH | ASTH1532W2
Turn lights on/off with just a simple touch.

WAVE® SWITCH | ASWV1532W2
Go germ-free. Turn lights on/off with a wave.

Outlets & Night Lights

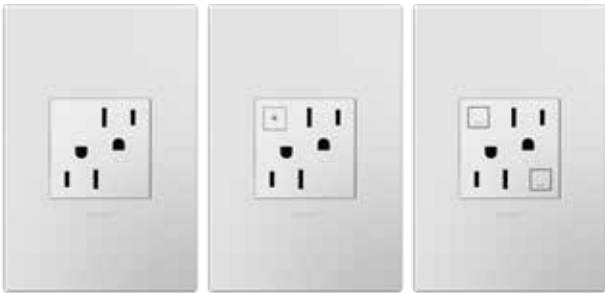

TAMPER-RESISTANT OUTLET | ARTR152W4


Upgrade from a standard outlet with discreet tamper-resistance.

ENERGY-SAVING ON/OFF OUTLET | ARPS152W4

Add style, while reducing energy waste. Outlet can be shut off when not in use to avoid pulling power in standby mode.

**TAMPER-RESISTANT SELF-TEST
GFCI OUTLET | AGFTR2152W4**

Get superior safety and superior style. Protects against electrical shock caused by ground-faults.

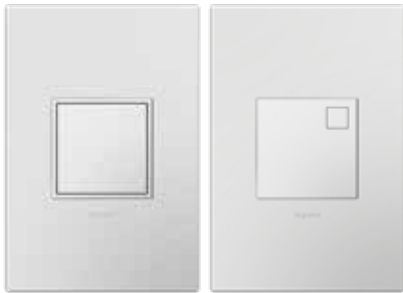

POP-OUT OUTLET | ARPTR151GW2

Pop it out to fit up-to-3 plugs simultaneously, then gently push back into the wall when not in use.

NIGHT LIGHT | AANLM24


Add built-in illumination for easier nighttime navigation.

PORTABLE NIGHT LIGHT/FLASHLIGHT | AARNL2

An in-wall night light that can be popped out for use as a flashlight.




USB Charging Solutions

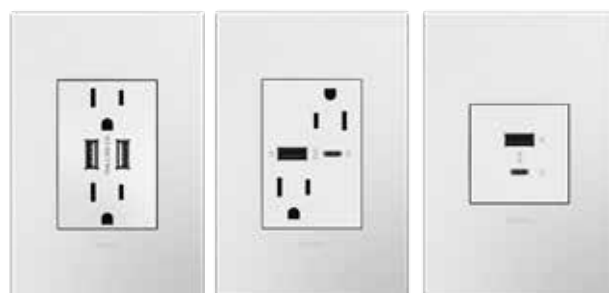

DUAL USB OUTLET, PLUS-SIZE | ARTRUSB153W4
Charge two devices simultaneously, without sacrificing a plug or needing a bulky adapter.

TAMPER-RESISTANT ULTRA-FAST USB TYPE-A/C OUTLET, PLUS-SIZE | ARTRUSB156ACW4
Charge your phone or tablets faster with an industry-leading 6 amps of power, without sacrificing a plug or needing a bulky adapter.

ULTRA-FAST USB TYPE-A/C OUTLET MODULE | ARUSB2AC6W4
Get faster USB charging with this module featuring both USB Type-A and Type-C ports.

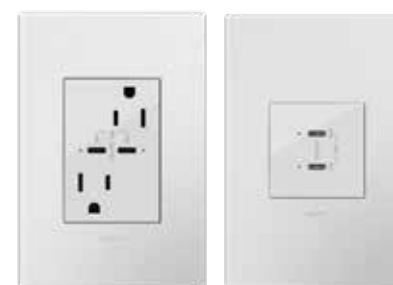

TAMPER-RESISTANT ULTRA-FAST PLUS POWER DELIVERY USB TYPE-C/C OUTLET, PLUS-SIZE | ARTRUSB15PD30W4
Maximize charging (up to 2x faster) with ultra-fast speed and advanced Power Delivery.

ULTRA-FAST PLUS POWER DELIVERY USB TYPE-C/C OUTLET MODULE | ARUSB30PDW4
Get future-proof charging that is up to 2X as fast, with this Power Delivery-enabled module featuring two USB Type-C ports.

Smart Lighting



works with alexa

works with Google Home


Works with Apple HomeKit



Manage lights and power, from anywhere, with the Legrand Home + Control app.




adorne® WITH Netatmo

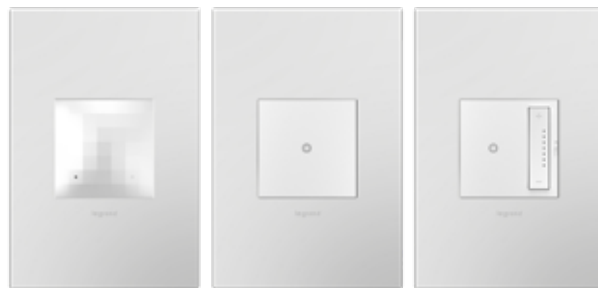

SMART GATEWAY WITH NETATMO | WNAH1W1
Start here to create a robust, dedicated network for advanced smart control throughout an entire home. Required for all “with Netatmo” smart lighting solutions. Surface-mount version also available.

SMART SWITCH WITH NETATMO | WNAL10W1
Get advanced control of your lights from any smart device, from anywhere. Plug-in version also available.

SMART TRU-UNIVERSAL DIMMER WITH NETATMO | WNAL50W1
This dimmer self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V). Plug-in version also available.

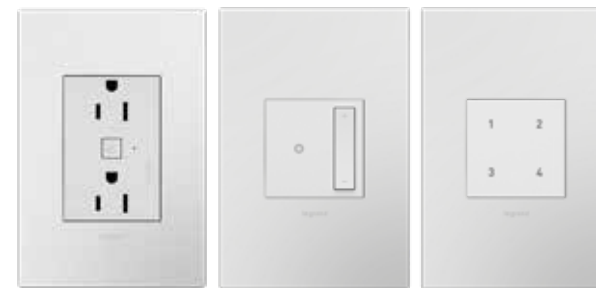

SMART OUTLET, PLUS-SIZE WITH NETATMO | WNAR153W1
Get advanced control of power from any smart device, from anywhere. One outlet is app-controlled, the other is always on. 15A and 20A versions available.

WIRELESS SMART DIMMER WITH NETATMO | WNAL63W1
Add to any wall or surface for easy 3-way dimming control. Battery-operated; no wiring required. Switch also available.

WIRELESS SMART SCENE CONTROLLER WITH NETATMO | WNACB40W1
Add to any wall or surface for one-tap control of four lighting scenes. Battery-operated; no wiring required.

Paddle

The Paddle design features a simple up-or-down action, allowing you to turn lights on and off with ease. Dimmers include a slider for dimming or brightening lights. Pair with a Locator Status Light to add illumination to your Paddle switch or dimmer. See page 25.

Now with lasting Microban® antimicrobial* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASPD1532W4 ASPD1532M4 ASPD1532G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120V	All Loads	 , RoHS
	ASPD2032W4 ASPD2032M4 ASPD2032G4		White Magnesium Graphite	20A, 120V	All Loads	 , RoHS
	ASPD1532W277 ASPD1532M277 ASPD1532G277		White Magnesium Graphite	15A, 277V	All Loads	 , RoHS
	ASPD2042W4 ASPD2042M4 ASPD2042G4	4-way switches work with two adorne switches OR with one adorne switch and one adorne dimmer.	White Magnesium Graphite	20A, 120V	All Loads	 , RoHS
	ASPD1542W277 ASPD1542M277 ASPD1542G277		White Magnesium Graphite	15A, 277V	All Loads	 , RoHS
	ADPD153LW2 ADPD153LM2 ADPD153LG2	LED Advanced Dimmer, Single- pole/3-way, No Neutral Required	White Magnesium Graphite	120V, 150W LED; 150W CFL/INC	LED**, CFL/INC	 , RoHS
	ADPD4FBL3P2W4 ADPD4FBL3P2M4 ADPD4FBL3P2G4	Single-pole/3-way.	White Magnesium Graphite	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	0-10V Light Fixtures	 , RoHS
	ASPD1531W4 ASPD1531M4 ASPD1531G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120V	All Loads	 , RoHS
	ASPD1531W277 ASPD1531M277 ASPD1531G277		White Magnesium Graphite	15A, 277V	All Loads	 , RoHS
	AAFN4S16AW4 AAFN4S16AM4 AAFN4S16AG4	Features four speeds. Includes de-hummer.	White Magnesium Graphite	1.6A, 120V	Paddle-Type Ceiling Fan	 , RoHS

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.

*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

**Not intended for ELV, MLV, or 0-10V loads

Whisper®

The Whisper design features classic, elegant lines and a gentle action. Whisper dimmers include a slide for dimming or brightening lights. Pair with a Locator Status Light to add illumination to your Whisper switch or dimmer. See page 25.

Now with lasting Microban® antimicrobial* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASWR1532W4 ASWR1532M4 ASWR1532G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120V	All Loads	 , RoHS
	ADWR703TUW4 ADWR703TUM4 ADWR703TUG4	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/ CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS

Wave®

The Wave switch features innovative technology combined with sleek, contemporary design. Simply wave your hand in front of the switch to turn lights on and off.

With its touch-free motion, the Wave is ideal for countertop areas in kitchens and bathrooms. It has a preset sensor distance of approximately 4". However, this can be easily adjusted to sense movement from 1" to 6" in front of switch.

Now with lasting Microban® antimicrobial* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASWV1532W2 ASWV1532M2 ASWV1532G2	Single-pole/3-way.	White Magnesium Graphite	15A, 120V, 1/2 Hp	All Loads	 , RoHS
	ASWV2032W2 ASWV2032M2 ASWV2032G2	Single-pole/3-way.	White Magnesium Graphite	20A, 120V, 3/4 Hp	All Loads	 , RoHS

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.

*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

sofTap®

The sofTap design features an innovative micro-movement sensor that turns lights on or off with a lighter push action. Dimmers include a unique paddle to adjust light levels.

Now with lasting Microban® antimicrobial* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASTP1532W4 ASTP1532M4 ASTP1532G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120 V, 1/2 Hp	All Loads	 , RoHS
	ADTP703T UW4 ADTP703T UM4 ADTP703TUG4	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS
	ADTP4FBL3PW4 ADTP4FBL3PM4 ADTP4FBL3PG4	Single-pole/3-way.	White Magnesium Graphite	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	0-10V Light Fixtures	 , RoHS

Touch®

The Touch design features a stunning translucent face and operates just like a smartphone - simply touch your finger to the circle to turn lights on or off. Dimmer version uses arrows on the right to adjust light levels.

The white Touch interface is created using a unique translucent material. In multi-gang installations, we recommend pairing white Touch switches and dimmers for optimal consistency.

Now with lasting Microban® antimicrobial* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASTH1532W2 ASTH1532M2 ASTH1532G2	Single-pole/3-way.	White Magnesium Graphite	15A, 120 V, 1/2 Hp	All Loads	 , RoHS
	ADTH703T UW4 ADTH703T UM4 ADTH703TUG4	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS
	ADTH4FBL3PW4 ADTH4FBL3PM4 ADTH4FBL3PG4	Single-pole/3-way.	White Magnesium Graphite	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	0-10V Light Fixtures	 , RoHS
	DIMBPASSv	This device is an adapter that can be installed at the dimmer or at the load that fixes most LED light anomalies such as flicker and ghosting.	Black	120V 60Hz 0.1 Amps		

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.
*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

SensaSwitch® + SensaDimmer


SensaSwitches include passive infrared (PIR) sensor technology, automatically turning lights on or off when you enter or leave a room. The design features an innovative micro-movement sensor that allows you to also manually turn on lights with a soft touch of the finger. SensaSwitches are available in three models:

- Auto-ON/Auto-OFF: Automatically turns lights on when you enter a room and off when you leave. (Occupancy Sensor)
- Manual-ON/Auto-OFF: Allows you to turn lights on when you enter a room and automatically turns them off when you leave. (Vacancy Sensor)
- Manual-ON/Timed-OFF: Allows you to turn lights on when you enter a room and select a time for lights to turn off (options include 10, 20, 30, and 60 minutes). (Timer)

The SensaDimmer turns lights on when you enter a room and off when you leave, but can be adjusted to become Manual-ON/Auto-OFF if desired.

Now with lasting Microban® antimicrobial* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASOS32W4 ASOS32M4 ASOS32G4	Single-pole/3-way. Time delay of 5-30 min. Occupancy Sensor (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V, 600W, 60 Hz, 1/6 Hp	All Loads	 , RoHS
	ASVS12W4 ASVS12M4 ASVS12G4	Single-pole/3-way. Time delay of 5-30 min. Vacancy Sensor (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V, 600W, 60 Hz, 1/6 Hp	All Loads	 , RoHS CA Title 24
	ASTM2W2 ASTM2M2 ASTM2G2	Single-pole/3-way. Time delay options include 10, 20, 30 or 60 min. (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V, 600W, 60 Hz, 1/6 Hp	All Loads	 , RoHS
	ADSM703HW2 ADSM703HM2 ADSM703HG2	Single-pole/3-way. Time delay of 5-30 min. Dimming Occupancy Sensor (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V 700W	Incandescent, Halogen	 , RoHS

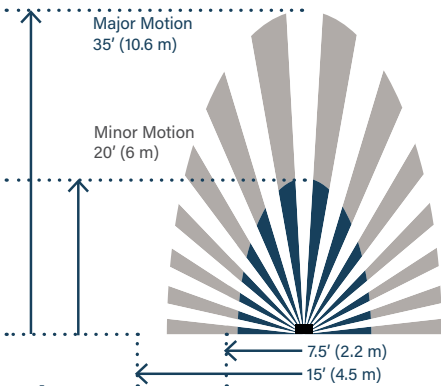

Coverage Area
The Occupancy Sensor, Vacancy Sensor, and SensaDimmer each have a maximum coverage range of 180 degrees and a coverage area of 600 sq. ft. The sensor must have a clear and unobstructed view of the coverage area. Objects blocking the sensor's lens may prevent detection thereby causing the light to turn off even though someone is in the area. Windows, glass doors, and other transparent barriers will obstruct the sensor's view and prevent detection.

*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

Outlets

Outlets from the adorne Collection feature a tamper-resistant design, complete with a patented black invi-shutter system. All 15A outlets also have a 20A feed or pass-through for installation flexibility.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
15A Single Outlet 	ARTR151W10 ARTR151M10 ARTR151G10	A dedicated tamper-resistant outlet for use with appliances or devices with larger plugs.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
		Pair with a Half-Size Night Light or Paddle Switch for greater functionality in a 1-Gang+ Wall Plate. 15A provides 20A pass-through.		20A, 125V 		
Tamper-Resistant Outlet 	ARTR152W4 ARTR152M4 ARTR152G4	Pair with a Half-Size Night Light or Paddle Switch for greater functionality in a 1-Gang+ Wall Plate. 15A provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
	ARTR202W4 ARTR202M4 ARTR202G4		White Magnesium Graphite	20A, 125V 	5-20R	
Tamper-Resistant Outlet, Plus-Size 	ARTR153W4 ARTR153M4 ARTR153G4	Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
Tamper-Resistant Self-Test GFCI Outlet 	AGFTR2152W4 AGFTR2152M4 AGFTR2152G4	GFCIs protect against serious injury due to electric shock. They are required by National Electrical Code in kitchens and bathrooms. All adorne GFCIs are self testing to meet the latest NEC requirement. 15A provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
	AGFTR2202W4 AGFTR2202M4 AGFTR2202G4		White Magnesium Graphite	20A, 125V 	5-20R	
Tamper-Resistant Self-Test GFCI Outlet, Plus-Size 	AGFTR2153W4 AGFTR2153M4 AGFTR2153G4	GFCIs protect against serious injury due to electric shock. They are required in kitchens and bathrooms. All adorne GFCIs are self testing to meet the latest NEC requirement. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
		Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations.				
Energy-Saving ON/OFF Outlet 	ARPS152W4 ARPS152M4 ARPS152G4	On/off switch allows you to save energy and stop the flow of power without unplugging your device. Perfect for kitchens, bathrooms, and computer rooms. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
Tamper-Resistant Dual Controlled Outlet 	ARCD152W10 ARCD152M10 ARCD152G10	This Plug Load outlet controls both receptacles, which will turn off for energy efficiency and cost savings. They are code-required, meet standards, and include permanent power markings. 15A provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
	ARCD202W10 ARCD202M10		White Magnesium	20A, 125V 	5-20R	
Tamper-Resistant Half Controlled Outlet 	ARCH152W10 ARCH152M10 ARCH152G10	This Plug Load outlet controls half the receptacle, featuring a factory-broken split-circuit tab, allowing half of the receptacle to turn off for energy efficiency and cost savings. They are code-required, meet standards, and include permanent power markings. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS

USB Charging

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Dual USB Outlet, Plus-Size 	ARTRUSB153W4 ARTRUSB153M4 ARTRUSB153G4	Perfect for charging multiple mobile devices. Provides 20A pass-through. Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations. Available in two versions: standard (without wall plate) or with an included wall plate in matching finish.	White Magnesium Graphite	3.1A, 5V DC 15A, 125V 	5-15R for NEMA	 , RoHS
	ARTRUSB153W4WP ARTRUSB153M4MP		(WITH WALL PLATE) White Magnesium			 , RoHS
Ultra-Fast USB Type-A/A Outlet 	ARUSB2AA6W4 ARUSB2AA6M4 ARUSB2AA6G4	Charge phones, tablets and more, faster, with 2 USB connections pulling 6 amps of power.	White Magnesium Graphite	6A 		 , RoHS
Ultra-Fast USB Type-A/C Outlet 	ARUSB2AC6W4 ARUSB2AC6M4 ARUSB2AC6G4	Charges phones, tablets and more, faster, with 6 amps of power via USB Types-A and C connections.	White Magnesium Graphite	6A 		 , RoHS
Tamper-Resistant Ultra-Fast USB Type-A/C Outlet, Plus-Size 	ARTRUSB156ACW4 ARTRUSB156ACM4 ARTRUSB156ACG4	Charges phones, tablets and more, faster, with 6 amps of power via USB Types-A and C connections. Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations.	White Magnesium Graphite	6A 15A, 125V 	5-15R for NEMA	 , RoHS
	ARTRUSB206ACW4 ARTRUSB206ACM4 ARTRUSB206ACG4		White Magnesium Graphite	6A 20A, 125V 	5-20R for NEMA	 , RoHS
Tamper-Resistant Ultra-Fast PLUS Power Delivery USB Type-C/C Outlet 	ARUSB30PDW4 ARUSB30PDM4 ARUSB30PDG4	Charge up to 2X faster with this module featuring advanced Power Delivery* technology in two future-proof USB Type-C ports. 30W power negotiation for the most optimal charge for devices.	White Magnesium Graphite	6A 		 , RoHS
Tamper-Resistant Ultra-Fast PLUS Power Delivery USB Type-C/C Outlet, Plus-Size 	ARTRUSB15PD30W4 ARTRUSB15PD30M4 ARTRUSB15PD30G4	Charges devices up to 2X faster by combining our ultra-fast speed with advanced Power Delivery* technology. Includes two future-proof USB Type-C ports. 30W power negotiation for the most optimal charge for devices. Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations.	White Magnesium Graphite	6A, 15A, 125V, 	5-15R for NEMA	 , RoHS
	ARTRUSB20PD30W4 ARTRUSB20PD30M4 ARTRUSB20PD30G4		White Magnesium Graphite	6A, 20A, 125V, 	5-20R for NEMA	 , RoHS

*Power Delivery enables connected devices to receive the precise amount of power needed for safely maximized charging speeds.



Pop-Out™ Outlet

Pop-Out Outlets require a special frame (included in package) and are not compatible with those used with adorne wall plates. **They require a deep box, such as Pass & Seymour SI22R, for installation or in a location that has a thick material like a kitchen backsplash, in a standard box.** Each 15A outlet includes capacity for three plugs.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Pop-Out Outlet, 1-Gang	ARPTR151GW2 ARPTR151GM2 ARPTR151GG2	Includes 1-gang frame for installation. Cannot be paired with other switches, dimmers, outlets, or accessories. 15A version provides 3 receptacles. 20A version provides 2 receptacles. Cannot be used in multi-gang installations.	White Magnesium Graphite	15A 	5-15R	, RoHS
	ARPTR201GW2 ARPTR201GM2 ARPTR201GG2		White Magnesium Graphite	20A 	5-20R	
Pop-Out Outlet, 2-Gang	ARPTR152GW2 ARPTR152GM2 ARPTR152GG2	Includes one Pop-Out Outlet and 2-gang frame for installation. Select this option to pair your Pop-Out Outlet with another adorne switch, dimmer, outlet, or accessory.	White Magnesium Graphite	15A 	5-15R	, RoHS



deQuorum™ Flip-Up Table Boxes

deQuorum Flip-Up Table Boxes provide flexibility in decor, communication connectivity options, and installation to meet specific functional and aesthetic needs. Flip-Up Table Boxes bring the modules above the work surface when in use for easy access. Available in a black powder coat or brushed stainless steel finish.
*For additional configurations, contact your local rep.


NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Field Wired Dequorum™ Single Flip Up Unit with USB	DQFF15UBK DQFF15UST	Unit includes one (1) 15A tamper resistant duplex receptacle with two (2) USB ports that provide 3.1A.	Black Stainless	15A, 125V	5-15R	, RoHS
Cord Ended Dequorum™ Single Flip Up Unit with USB	DQFP15UBK DQFP15UST	Unit includes one (1) 15A black tamper-resistant duplex receptacle with two (2) USB ports that provide 3.1A. Unit comes with a 6' (1.83m) cord. Comes with a black powder coat finish.	Black Stainless	15A, 125V	5-15R	, RoHS
Cord Ended Dequorum™ Single Flip Up Unit	DQFP15BK DQFP15ST	Unit includes one (1) 15A black tamper-resistant duplex receptacle. Unit comes with a 6' (1.83m) cord. Comes with a black powder coat finish.	Black Stainless	15A, 125V	5-15R	, RoHS



Furniture Power Centers


Furniture Power Centers offer endless design possibilities by allowing power and charging to be built directly into furniture. Available options can blend in seamlessly or add a beautiful accent to your furniture or space. Add power, charging and more directly into headboards, night stands or seating.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Furniture Power, Outlet and USB Port	AD1-RU-W AD1-RU-M	Easily add power and charging to furniture. 1 tamper-resistant outlet and 1 USB charging port in a magnesium finish. Wall plate sold separately. Comes standard with 8 foot cord with right angle plug.	White Magnesium	Receptacles: 15A 120V USB charging ports: 2.4A, 5Vdc each	5-15R	, RoHS
Furniture Power, Outlet and 2 USB Ports	AD2-2UR-W AD2-2UR-M	Easily add power and charging to furniture. 1 tamper-resistant outlet and 2 USB charging ports in a magnesium finish. Wall plate sold separately. Comes standard with 8 foot cord with right angle plug.	White Magnesium	Receptacles: 15A 120V USB charging ports: 2.4A, 5Vdc each	5-15R	, RoHS
Furniture Power, 2 Outlets and 2 USB Ports	AD3-R2UR-W AD3-R2UR-M	Easily add power and charging to furniture. 2 tamper-resistant outlets and 2 USB charging ports in a magnesium finish. Wall plate sold separately. Comes standard with 8 foot cord with right angle plug.	White Magnesium	Receptacles: 15A 120V USB charging ports: 2.4A, 5Vdc each	5-15R	, RoHS

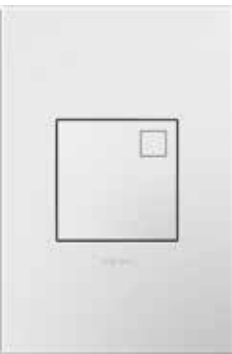

Illumination Accessories

You've never seen a night light that hides itself so cleverly, yet responds so elegantly to a simple touch. Or one that can be lifted from its home on your wall to double as a carry-around flashlight. When it comes to brilliant solutions, adorne really shines. All night lights include ambient light level sensors. Each features a range of settings, including: Always Off, Low, Medium and High. If set to Low, Medium or High, the night light's LED will only be visible when the ambient room is dark. To change the selected setting, simply push on the square in the upper right-hand corner of the night light.

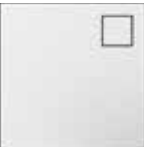NAME	PART NUMBER	DESCRIPTION	COMPLIANCE
Night Light, Half-Size 	AANLM14	Features a soft, glowing LED light. Pair with a switch or outlet in a 1-Gang+ Wall Plate for greater functionality. Light levels include: Always Off Low Medium High	 , RoHS
Night Light 	AANLM24	Features a soft, glowing LED light. Light levels include: Always Off Low Medium High	 , RoHS
Portable Night Light/Flashlight 	AARNL2	Simply push on this innovative night light to remove it from the wall and use it as a flashlight. Device recharges while mounted in wall and operates for up to 10 hours during a power failure. Includes light level options listed above, as well as Flashlight Mode, which is activated only when device is removed from the wall.	 , RoHS



In-wall Night Light function



Press on Night Light to remove from wall





Portable flashlight function



Locator Status Light: Find Us in the Dark

NAME	PART NUMBER	DESCRIPTION	COMPLIANCE
Locator Status Light 	AALS6 AALS277 (277 VAC)	Add a stylish, small locator light to your Paddle, or Whisper switch or dimmer and you'll never again have to slide your hand across the wall trying to find that switch. The locator light is a standard feature of all other switches and dimmers. It can be disabled if desired. Locator light is on when the load is off and off when the load is on.	 , RoHS

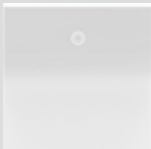 OPTIONAL					
					
Paddle Optional Accessory	Whisper Optional Accessory	sofTap Standard Feature	SensaSwitch Standard Feature	Touch Standard Feature	Wave Standard Feature

SMART LIGHTING



Color Change Kits - adorne

NAME	PART NUMBER	INSTALLATION / WORKS WITH	DESCRIPTION	COLOR
Smart Switch with Netatmo Color Change Kit	WNAL10CKIT*	WNAL10*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Remote Smart Switch with Netatmo Color Change Kit	WNAL23CKIT*	WNAL23* WNAL24*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Dimmer with Netatmo Color Change Kit	WNAL50CKIT*	WNAL50*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Remote Smart Dimmer with Netatmo Color Change Kit	WNAL63CKIT*	WNAL63* WNAL64*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Home/Away Switch with Netatmo Color Change Kit	WNAL33CKIT*	WNAL33* WNAL34*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Wake/Sleep Switch with Netatmo Color Change Kit	WNAL43CKIT*	WNAL43* WNAL44*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)"
Smart Scene Controller with Netatmo Color Change Kit	WNACB40CKIT*	WNACB40* WNACB46*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)

adorne with Netatmo

Control lights and power, from anywhere, with the ultra-reliable smart lighting solution optimized for whole-home use. Build a system in three easy steps: 1) select a Gateway; 2) select primary devices; and 3) select add-on devices. Works with Amazon Alexa, Google Home and Apple HomeKit. Compatible with radiant with Netatmo.


 
 
STEP 1: Select a Gateway

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Smart Gateway with Netatmo 	WNAH1W1 WNAH1M1 WNAH1G1	Creates a robust and dedicated network as the foundation of an adorne with Netatmo smart lighting solution.	White Magnesium Graphite	120V		 , RoHS
Smart Surface-Mount Gateway with Netatmo 	WNAH2W1 WNAH2M1 WNAH2G1	Creates a robust and dedicated network as the foundation of an adorne with Netatmo smart lighting solution. Installs beside an outlet or switch in a single-gang electrical box. Ideal for remodels.	White Magnesium Graphite	120V		 , RoHS
Smart Switch with Netatmo 	WNAL10W1 WNAL10M1 WNAL10G1	Controls lights from anywhere. Gateway required.	White Magnesium Graphite	15A, 120V		 , RoHS
Smart Tru-Universal Dimmer with Netatmo 	WNAL50W1 WNAL50M1 WNAL50G1	Controls lights from anywhere. Gateway required. Trim and phase adjustments are made in the Home+Control app. Works with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/ CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W FWD/250W REV (not compatible with 0-10VLED drivers), EFL: 5.5A	 , RoHS
Smart Outlet with Netatmo, Plus-Size 	WNAR153W1 WNAR153M1 WNAR153G1 WNAR203W1 WNAR203M1 WNAR203G1	Control power from anywhere. Two methods of install: 1. Wire for one outlet always on, one controlled; 2. Wire for downstream control of all outlets. Pair with a Wireless Smart Switch for on-wall control. Gateway required.	White Magnesium Graphite White Magnesium Graphite	15A, 125V,  20A, 125V, 	5-15R 5-20R	 , RoHS
Smart Plug-In Switch with Netatmo 	WNP10	Plugs into an existing outlet to provide smart control of lamps or small appliances. Gateway required.	White			 , RoHS
Smart Plug-In Tru-Universal Dimmer with Netatmo 	WNP20	Plugs into an existing outlet to provide smart dimming control. Gateway required. Trim and phase adjustments are made in the Home+Control app. Works with virtually any dimmable bulb or fixture (excludes 0-10V).	White	120V 450W LED/ CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W FWD/250W REV (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture. See new adorne Color Change Kits on page 25

STEP 3: Select Add-on Devices

  KITS

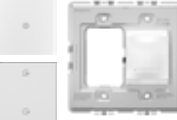NAME	PART NUMBER	INSTALLATION	DESCRIPTION	COLOR/FINISH	COMPLIANCE
Remote Smart Switch with Netatmo 	WNAL23W1 WNAL23M1 WNAL23G1 WNAL24W1	Wireless (Battery-Operated) Wired	For easy 3-way control. Must be paired with a primary Smart Switch or Outlet with Netatmo. Can also be used as a master switch to control multiple wired Smart Switches with Netatmo.	White Magnesium Graphite	 , RoHS
Remote Smart Dimmer with Netatmo 	WNAL63W1 WNAL63M1 WNAL63G1 WNAL64W1	Wireless (Battery-Operated) Wired	For easy 3-way control. Must be paired with a primary wired (or plug-in) Smart Tru-Universal Dimmer with Netatmo. Can also be used as a master dimmer to control multiple primary Smart Tru-Universal Dimmers with Netatmo.	White Magnesium Graphite	 , RoHS
Smart Scene Controller with Netatmo 	WNACB40W1 WNACB40M1 WNACB40G1 WNACB46W1	Wireless (Battery-Operated) Wired	"Controls 4 customizable lighting scenes with a single touch. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep."	White Magnesium Graphite	 , RoHS
Smart Home/Away Switch with Netatmo 	WNAL33W1 WNAL33M1 WNAL33G1 WNAL34W1	Wireless (Battery-Operated) Wired	Controls 2 scenes of multiple lights. Turn the lights on (or off), simultaneously, with just a single tap. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Magnesium Graphite	 , RoHS
Smart Wake/Sleep Switch with Netatmo 	WNAL43W1 WNAL43M1 WNAL43G1 WNAL44W1	Wireless (Battery-Operated) Wired	Controls 2 scenes of multiple lights. Turn the lights on (or off), simultaneously, with just a single tap. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Magnesium Graphite	 , RoHS
 4-Scene Pocket Remote Control with Netatmo	067695	Wireless (Battery-Operated)	Control up to four full lighting scenes with a touch with this portable smart remote and key fob. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	Black	
 Wireless Motion Sensor with Netatmo	064875	Wireless (Battery-Operated)	Automatically turns lights on/off when motion is detected/absent for added safety and efficiency. Battery-operated. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo.	White	
Smart Switch Starter Kit with Netatmo 	WNAH10KITW1 WNAH10KITM1 WNAH10KITG1		Kit includes (1) Smart Switch with Netatmo, (1) Smart Surface-Mount Gateway with Netatmo, (1) Home/Away Wireless Smart Switch with Netatmo Rating: 15A, 125V	White Magnesium Graphite	 , RoHS

Blank Module

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH
Half-Size Blank	AABK1W4 AABK1M4 AABK1G4	Use this blank insert to give your project a complete, finished look. Pair it with other half-size devices, like the Night Light, Paddle Switch or USB, in a 1-gang wall plate.	White Magnesium Graphite



Keystone Frames

For a consistent look throughout the project, select an adorne keystone frame to enable audio, video and data connectivity in an adorne wall plate. Simply pair a 1-port, 2-port or 4-port frame with any keystone inserts shown on the next page and then mount in an adorne wall plate for a complete installation.

NAME	PART NUMBER	COLOR/FINISH
1-Port Frame	AC1PFW1 AC1PFM1 AC1PFG1	White Magnesium Graphite
2-Port Frame	AC2PFW1 AC2PFM1 AC2PFG1	White Magnesium Graphite
4-Port Frame	AC4PFW1 AC4PFM1	White Magnesium
In-Wall Cable Access Port	ACBRSTPW1 ACBRSTPM1	White Magnesium



1-Port Frame



2-Port Frame



4-Port Frame



In-Wall Cable Access Port

Keystone Inserts

NAME	PART NUMBER	COLOR/FINISH
Cat 5e RJ45 Data/Phone Insert	AC5ERJ45W1 AC5ERJ45M1	White Magnesium
Cat 5e RJ45 Data Coupler Insert	AC5ERJ45CW1 AC5ERJ45CM1	White Magnesium
Cat 6 RJ45 Data Insert	AC6RJ45W1 AC6RJ45M1 AC6RJ45G1	White Magnesium Graphite
RJ25 Phone Jack	ACRJ25W1 ACRJ25M1	White Magnesium
Component Video RCA to F Kit	ACRGBRCAFW1 ACRGBRCAFM1	White Magnesium
Composite Video RCA to F-Connector	ACYRCAFW1 ACYRCAFM1	White Magnesium



Cat 5e RJ45 Data Coupler Insert



Cat 6 RJ45 Data Insert



RJ25 Phone Jack



Component Video RCA to F Kit



Composite Video RCA to F-Connector



NAME	PART NUMBER	COLOR/FINISH
HDMI Keystone Coupler	ACHDMIW1 ACHDMIM1	White Magnesium
Single Keystone Speaker Connector	ACSSIW1 ACSSIM1	White Magnesium
Speaker Binding Posts	ACABPW1 ACABPM1	White Magnesium
Subwoofer RCA to F-Connector	ACPRCAFW1 ACPRCAFM1	White Magnesium
Video F-Connector	ACNRFCW1 ACNRFCM1 ACNRFCG1	White Magnesium Graphite
Blank Keystone Insert (4-Pack)	ACBLKW4 ACBLKM4	White Magnesium



Single Keystone Speaker Connector



Speaker Binding Posts



Subwoofer RCA to F-Connector



Video F-Connector



Blank Keystone Insert (4-Pack)



Modular Unit Dimensions

Half-Size Dimensions

45mm (1.77")
22.5mm (.89")

Full-Size Dimensions

45mm (1.77")
45mm (1.77")

Plus-Size Dimensions

67.5mm (2.66")
45mm (1.77")

- The basic building block of the system is a half-size unit (45mm x 22.5mm).
- All devices have either half-size or full-size front faces.
- Devices can also have half-size, full-size or plus-size back bodies.

- Most switches, dimmers and outlets are in the full-size format (45mm x 45 mm). This is the standard adorne proprietary "45" opening.
- Select outlets are available with a plus-size front face (67.5mm x 45mm) for easier access to power and/or USB ports.
- Plus-size devices must be paired with 1-Gang+ wall plates.

Front Face and Back Body Modular Sizes

SWITCHES

NAME	FRONT FACE SIZE	BACK BODY SIZE
Paddle Switch, 2-Module	Full-Size	Full-Size
Paddle Switch, 1-Module	Half-Size	Half-Size
Whisper Switch	Full-Size	Full-Size
sofTap Switch	Full-Size	Plus-Size
SensaSwitch	Full-Size	Plus-Size
Touch	Full-Size	Plus-Size
Wave	Full-Size	Plus-Size

DIMMERS

NAME	FRONT FACE SIZE	BACK BODY SIZE
Paddle	Full-Size	Plus-Size
Whisper	Full-Size	Plus-Size
sofTap	Full-Size	Plus-Size
SensaDimmer	Full-Size	Plus-Size
Touch	Full-Size	Plus-Size
Paddle Fan Speed Control	Full-Size	Plus-Size

OUTLETS

NAME	FRONT FACE SIZE	BACK BODY SIZE
Tamper-Resistant Outlet, Full-Size	Full-Size	Full-Size
Tamper-Resistant Outlet, Plus-Size	Plus-Size	Plus-Size
GFCI Outlet, Full-Size	Full-Size	Plus-Size
GFCI Outlet, Plus-Size	Plus-Size	Plus-Size
Energy-Saving ON/OFF Outlet	Full-Size	Full-Size
Pop-Out Outlet	Full-Size	Plus-Size
Ultra-Fast USB Outlet, Plus-Size	Plus-Size	Plus-Size
Ultra-Fast Plus Power Delivery USB Outlet, Plus-Size	Plus-Size	Plus-Size

ILLUMINATION

NAME	FRONT FACE SIZE	BACK BODY SIZE
Night Light, Half-Size	Half-Size	Half-Size
Night Light, Full-Size	Full-Size	Full-Size
Portable Night Light/Flashlight	Full-Size	Plus-Size

Ways to Configure Various Device Sizes

1-GANG

Half-Size Paddle Switch + Half-Size Paddle Switch

Half-Size Night Light + Half-Size Paddle Switch

1-GANG+

Half-Size Night Light + Full-Size Outlet

Plus-Size Outlet

2-GANG

Full-Size Paddle Switch + Full-Size Outlet

3-GANG

Full-Size Paddle Switch + Full-Size Paddle Switch + Full-Size Paddle Dimmer

4-GANG

Full-Size Paddle Switch + Full-Size Paddle Switch + Full-Size Paddle Dimmer + Full-Size Paddle Fan Speed Control

R REAL MATERIALS

CM CAST METALS

P PLASTIC



Black Stainless



Brushed Stainless



Custom with Magnesium Trim



Custom with White Trim



Macassar



Mirror



Mirror Black



Mirror White



Mirror White, White-on-White



Slate Linen



Spiraled Stainless



Rustic Grey



True Linen



Copper



Brushed Black Nickel



Brushed Satin Brass



Brushed Stainless Steel



Coffee



Matte Antique Copper



Satin Black



Oil-Rubbed Bronze



Satin Nickel



Black Nickel



Gloss White



Gloss White, White-on-White



Matte White



Bronze



Black Ink



Oatmeal



Greige



Titanium



Magnesium



Graphite



Pale Blue



Rosa



Peachy



Mystic



Evergreen

REAL MATERIALS



Real Materials

These adorne Wall Plates add unique beauty to any space with contemporary options like stainless and mirror, as well as natural materials like linen and wood.

NAME	GANGS	PART NUMBER
Black Stainless	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2BLS4 AWM1G3BLS4 AWM2GBLS4 AWM3GBLS4 AWM4GBLS4
Brushed Stainless	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MS4 AWM1G3MS4 AWM2GMS4 AWM3GMS4 AWM4GMS4
Custom with Magnesium Trim	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2M4 AWM1G3M4 AWM2GM4 AWM3GM4 AWM4GM4
Custom with White Trim	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2W4 AWM1G3W4 AWM2GW4 AWM3GW4 AWM4GW4
Macassar	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MA4 AWM1G3MA4 AWM2GMA4 AWM3GMA4 AWM4GMA4
Mirror	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MR1 AWM1G3MR1 AWM2GMR1 AWM3GMR1 AWM4GMR1
Mirror Black	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MB4 AWM1G3MB4 AWM2GMB4 AWM3GMB4 AWM4GMB4

NAME	GANGS	PART NUMBER
Mirror White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MW4 AWM1G3MW4 AWM2GMW4 AWM3GMW4 AWM4GMW4
Mirror White, White-on-White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MWW4 AWM1G3MWW4 AWM2GMWW4 AWM3GMWW4 AWM4GMWW4
Rustic Grey	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2RG4 AWM1G3RG4 AWM2GRG4 AWM3GRG4 AWM4GRG4
Slate Linen	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2SL4 AWM1G3SL4 AWM2GSL4 AWM3GSL4 AWM4GSL4
Spiraled Stainless	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2SP4 AWM1G3SP4 AWM2GSP4 AWM3GSP4 AWM4GSP4
True Linen	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2TL4 AWM1G3TL4 AWM2GTL4 AWM3GTL4 AWM4GTL4
Copper	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2CU4 AWM1G3CU4 AWM2GCU4 AWM3GCU4 AWM4GCU4

CAST METALS



Cast Metals

Cast metal Wall Plates from the *adorne* Collection are hand-crafted by artisans, making them unique and distinctive. These slight variations in finish and color add to the rich beauty of the *adorne* cast metal offering.

NAME	GANGS	PART NUMBER
Black Nickel	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2BLN4 AWC1G3BLN4 AWC2GBLN4 AWC3GBLN4 AWC4GBLN4
Brushed Black Nickel	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2BBN4 AWC1G3BBN4 AWC2GBBN4 AWC3GBBN4 AWC4GBBN4
Brushed Satin Brass	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2BSB4 AWC1G3BSB4 AWC2GBSB4 AWC3GBSB4 AWC4GBSB4
Brushed Stainless Steel	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2BS4 AWC1G3BS4 AWC2GBS4 AWC3GBS4 AWC4GBS4
Coffee	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2COF4 AWC1G3COF4 AWC2GCOF4 AWC3GCOF4 AWC4GCOF4

NAME	GANGS	PART NUMBER
Matte Antique Copper	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2MAC4 AWC1G3MAC4 AWC2GMAC4 AWC3GMAC4 AWC4GMAC4
Satin Black	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2SBL4 AWC1G3SBL4 AWC2GSBL4 AWC3GSBL4 AWC4GSBL4
Oil-Rubbed Bronze	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2OB4 AWC1G3OB4 AWC2GOB4 AWC3GOB4 AWC4GOB4
Satin Nickel	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2SN4 AWC1G3SN4 AWC2GSN4 AWC3GSN4 AWC4GSN4



Plastics

Available in a variety of classic and contemporary colors, adorne plastic Wall Plates provide the perfect finishing touch to any installation.

NAME	GANGS	PART NUMBER	NAME	GANGS	PART NUMBER
 Gloss White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2WH6 AWP1G3WH4 AWP2GWH4 AWP3GWH4 AWP4GWH4 AWP5GWH1 AWP6GWH1	 Titanium	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2TM6 AWP1G3TM4 AWP2GTM4 AWP3GTM4 AWP4GTM4 AWP5GTM1 AWP6GTM1
 Gloss White, White-on-White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2WHW10 AWP1G3WHW4 AWP2GWHW10 AWP3GWHW4 AWP4GWHW4 AWP5GWHW1 AWP6GWHW1	 Bronze	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2BR6 AWP1G3BR4 AWP2GBR4 AWP3GBR4 AWP4GBR4 AWP5GBR1 AWP6GBR1
 Matte White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2PW4 AWP1G3PW4 AWP2GPW4 AWP3GPW4 AWP4GPW4 AWP5GPW1 AWP6GPW1	 Greige	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2GG4 AWP1G3GG4 AWP2GGG4 AWP3GGG4 AWP4GGG4 AWP5GGG1 AWP6GGG1
 Magnesium	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2MG6 AWP1G3MG4 AWP2GMG4 AWP3GMG4 AWP4GMG4 AWP5GMG1 AWP6GMG1	 Pale Blue	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2BL6 AWP1G3BL4 AWP2GBL4 AWP3GBL4 AWP4GBL4 AWP5GBL1 AWP6GBL1
 Graphite	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2GR6 AWP1G3GR4 AWP2GGR4 AWP3GGR4 AWP4GGR4 AWP5GGR1 AWP6GGR1	 Oatmeal	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2OM AWP1G3OM AWP2GOM AWP3GOM AWP4GOM AWP5GOM AWP6GOM
 Evergreen	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2EG AWP1G3EG AWP2GEG AWP3GEG AWP4GEG AWP5GEG AWP6GEG	 Peachy	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2PY AWP1G3PY AWP2GPY AWP3GPY AWP4GPY AWP5GPY AWP6GPY
 Mystic	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2MY AWP1G3MY AWP2GMY AWP3GMY AWP4GMY AWP5GMY AWP6GMY	 Rosa	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2RA AWP1G3RA AWP2GRA AWP3GRA AWP4GRA AWP5GRA AWP6GRA
			 Black Ink	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2NK4 AWP1G3NK4 AWP2GNK4 AWP3GNK4 AWP4GNK4 AWP5GNK1 AWP6GNK1

FINISHES

M

Matte

S

Satin

G

Gloss

The adorne Frame System

The frame is the foundation upon which the adorne modular system is built. It is manufactured with high-strength galvanized metal and includes a ground wire.

Frames include plastic spacers. The spacers remain in place for devices with full size back bodies. They must be removed for devices with plus size back bodies, such as dimmers and GFCI outlets.

The frame completes the enclosure, providing a safe installation during the construction phase and allowing the wall plate to be installed at the end of the project.

Each frame includes a leaded ground that supports the full adorne system. Most switches, outlets and wall plates (including cast metals) are automatically grounded to the frame, saving time and ensuring a safe and reliable ground path.



1-Gang, Full Size with Spacers



1-Gang, Plus Size without Spacers



2-Gang with Spacers



3-Gang with Spacers



4-Gang with Spacers



5-Gang with Spacers



6-Gang with Spacers

Mounting Frames

NAME	PART NUMBER
1-Gang Mounting Frame	AF1G
2-Gang Mounting Frame	AF2G
3-Gang Mounting Frame	AF3G
4-Gang Mounting Frame	AF4G
5-Gang Mounting Frame	AF5G
6-Gang Mounting Frame	AF6G

The adorne Modular System

Complete versatility and unmatched flexibility

adorne fits in all existing NEMA-approved wallboxes.*

The frame is grounded.

Device snaps into the frame and is automatically grounded**. It self-aligns without any screws.

Standard Wallbox

Ground Wire

Frame

Device

Wall Plate



Wall plate snaps onto frame; no screws required.

Modular system solves device alignment problems, improving fit and finish in multi-gang installations.

* Does not apply to Pop-Out Outlet.
** Does not apply to Pop-Out Outlet, 20A Outlet, or 20A GFCI Outlet.

Devices simply snap into the frame from the front. During installation, screw the frame to the box, then pull the wires through the frame and wire the device. Then, simply snap the device into the frame.





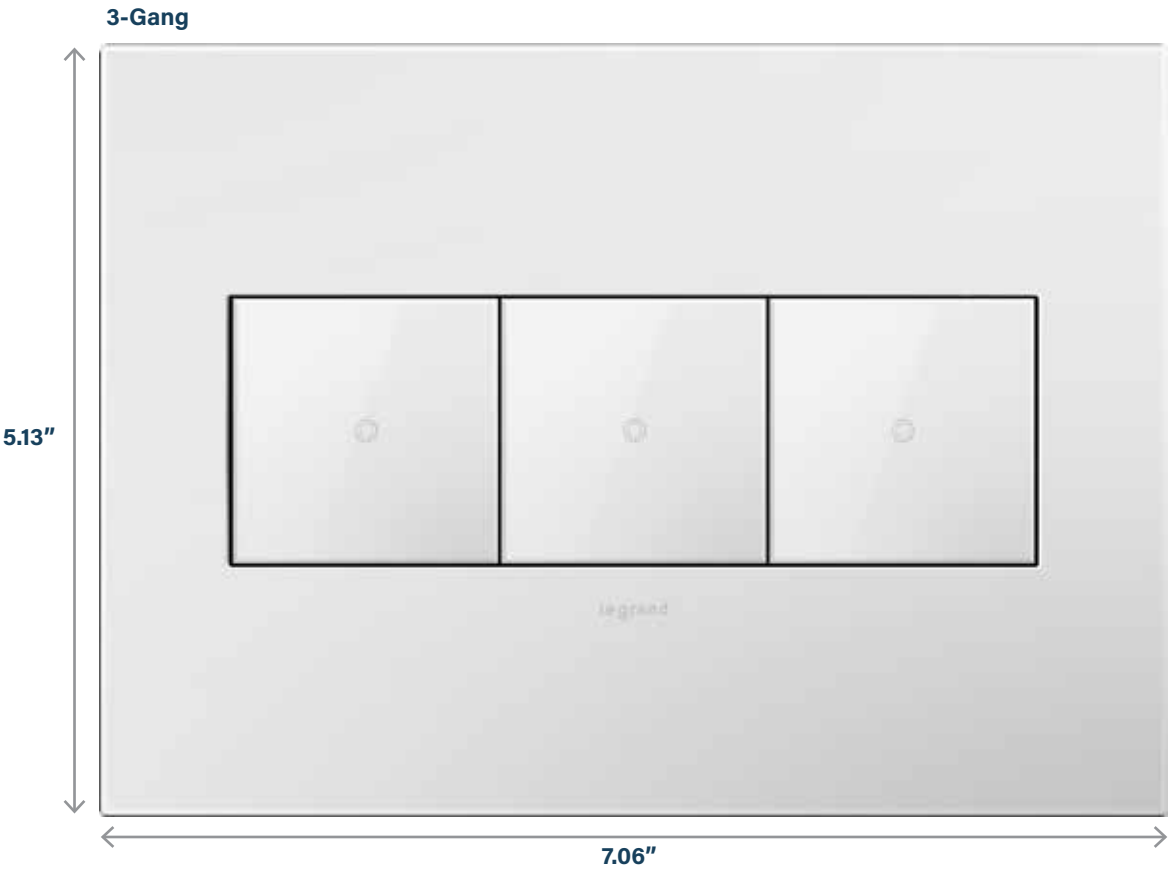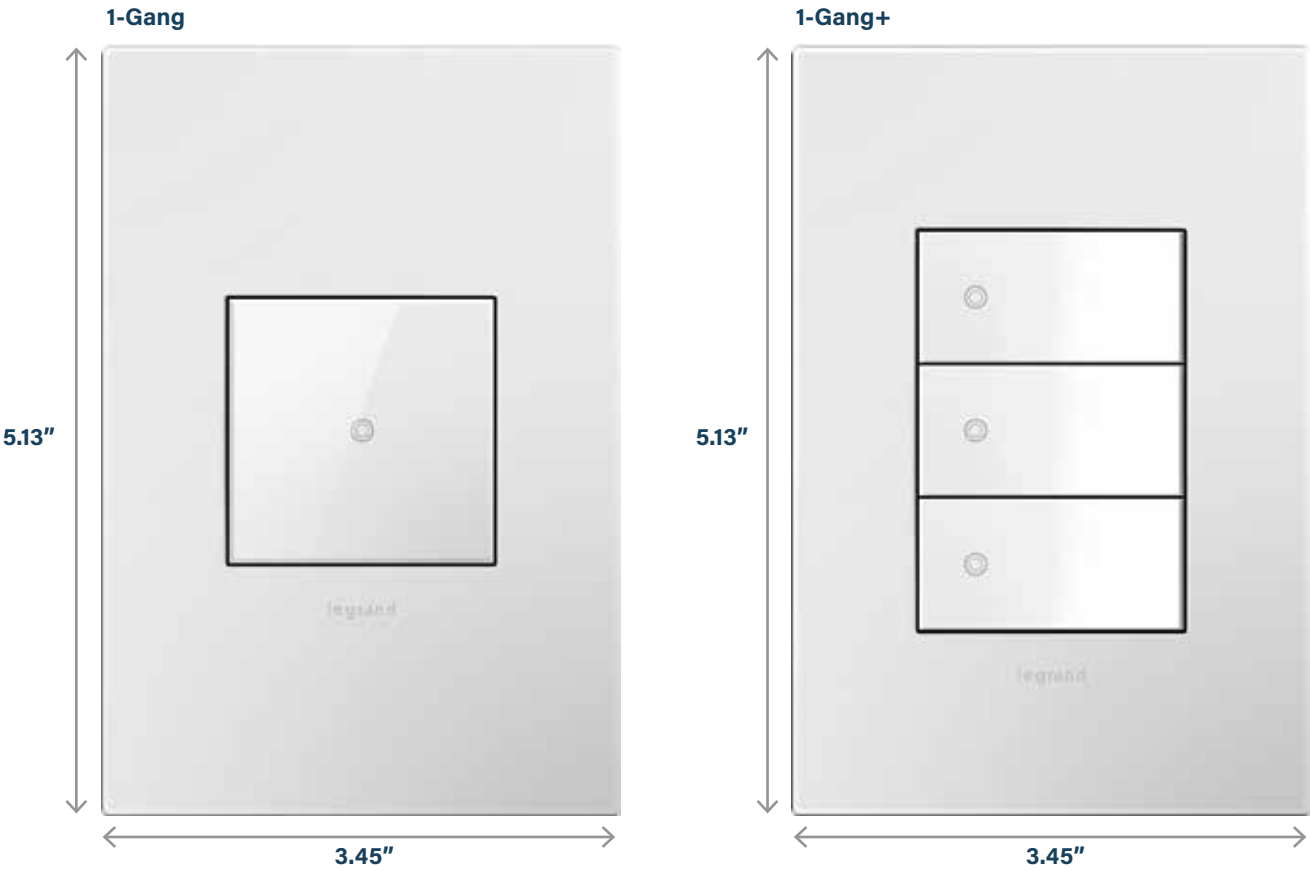

Wall Plates

Available in six gang sizes, adorne wall plates provide the perfect complement to adorne switches, dimmers, outlets and accessories. The collection includes a variety of finishes, from cast metals like Satin Nickel and Oil-Rubbed Bronze to real materials such as linen and wood. In addition, the collection includes a full offering of plastic plates in contemporary and classic colors, as well as three innovative Soft Touch finishes. Each wall plate is packaged with a mounting frame to enable easy installation when paired with a device. All plates are screwless and simply snap onto the included metal frame. See page 40 for more information on the adorne frame system.

All adorne wall plates are UL and ETL-approved. 5- and 6-Gang wall plates are not available in all colors.

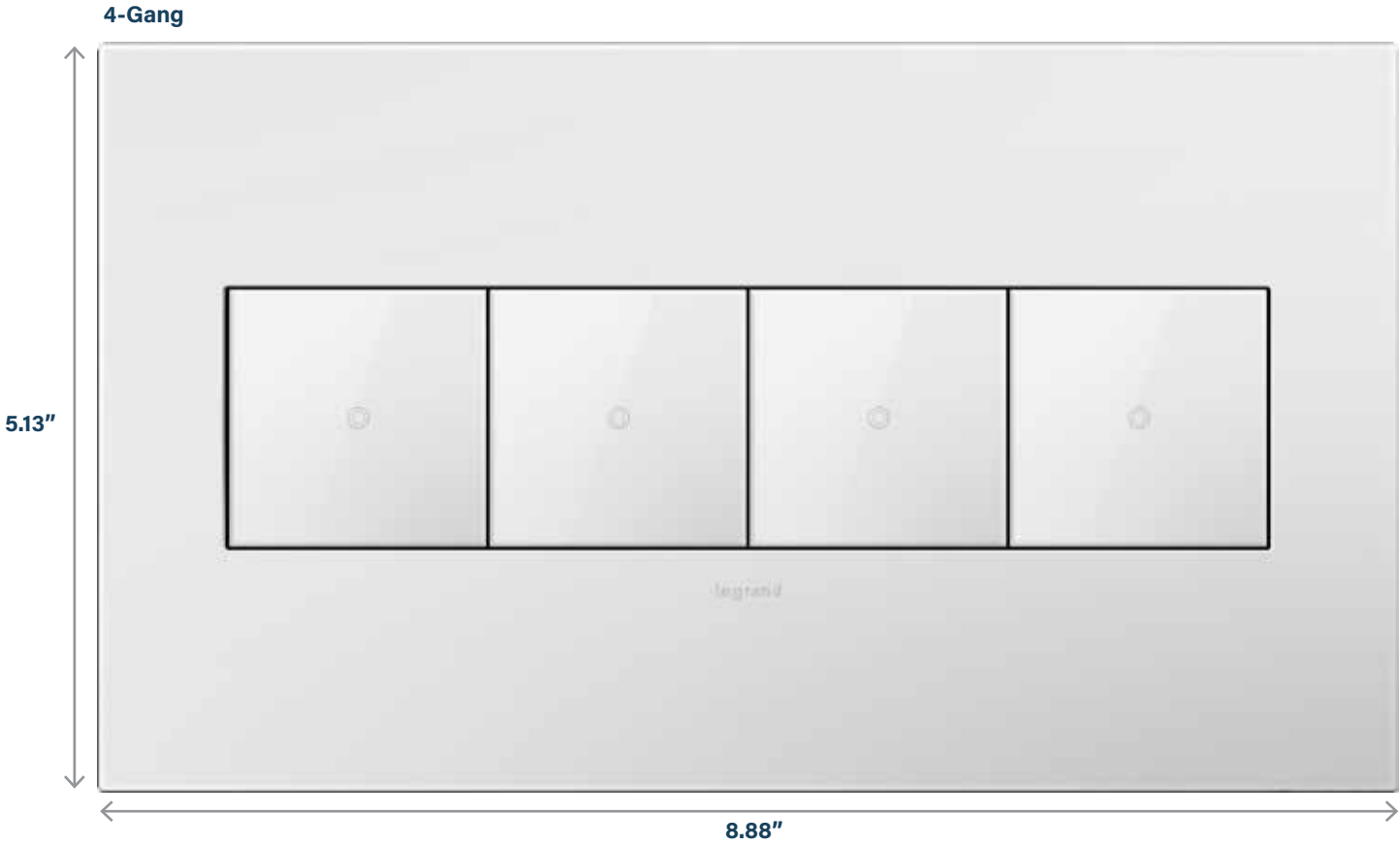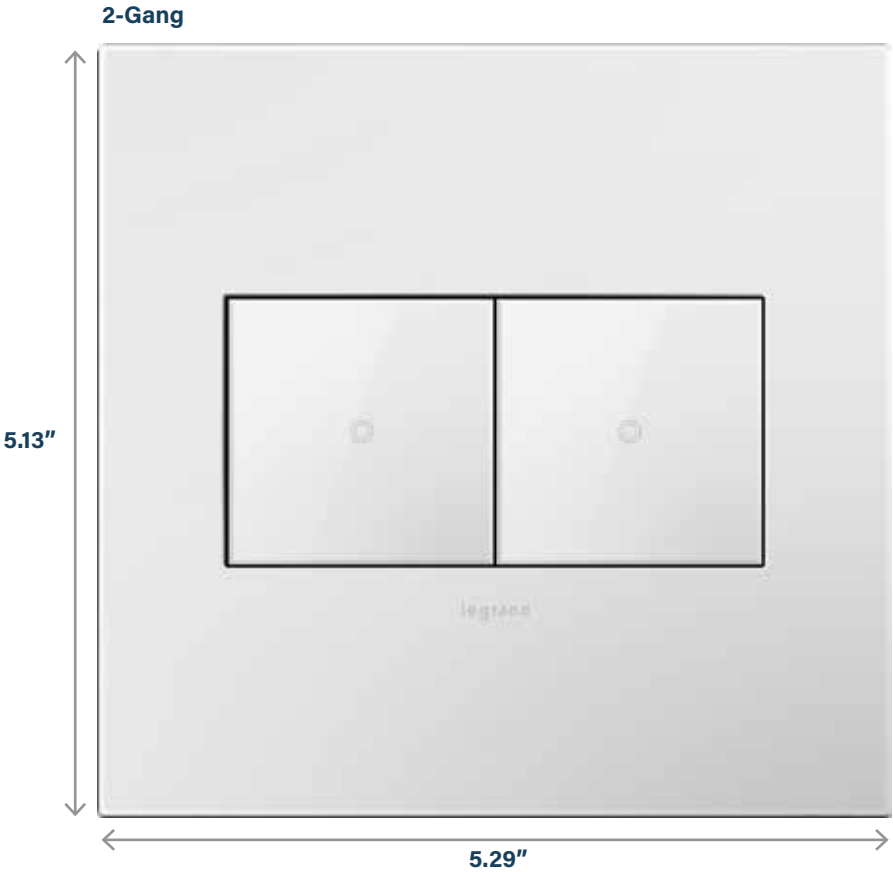

5-Gang
5.13" x 10.7"



6-Gang
5.13" x 12.5"



legrand.us/lightingcontrols



youtube.com/legrand



facebook.com/LegrandNA



instagram.com/legrandna



Electrical Wiring Systems

60 Woodlawn Street
West Hartford, CT
061101.877.BY.LEGRAND (295.3472)
www.legrand.us